

## Tube clamps, straight, aluminium

### Item description/product images



### Description

#### Material:

Cast aluminium.

DIN 7984 screws and DIN 985 nuts, steel.

#### Version:

Vibratory ground.

Screws and nuts electro zinc-plated.


#### On request:

Clamping levers for tightening.

#### Accessory:

- Round and square tubes K0493

### Drawings

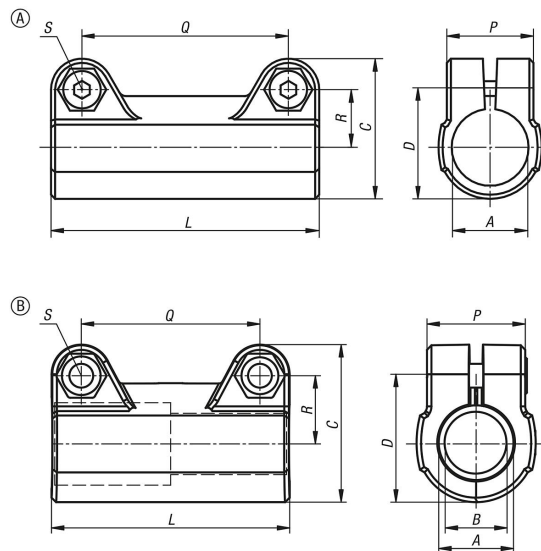

### Overview of items

#### Tube clamps, straight, aluminium

Order No.	Form	A	B	C	D	L	P	Q	R	S
K0483.52020	A	20,1	-	53	40	80	33	60	22,5	M8x25
K0483.52525	A	25,1	-	53	40	80	33	60	22,5	M8x25
K0483.53030	A	30,1	-	53	40	80	33	60	22,5	M8x25
K0483.54040	A	40,17	-	73	56	120	40	94	32	M10x30
K0483.55050	A	50,22	-	84	66	140	45	114	38	M10x35
K0483.56060	A	60,27	-	103	80	150	58	118	47	M12x45
K0483.53025	B	30,1	25,1	53	40	80	33	60	22,5	M8x25
K0483.54032	B	40,17	32,15	73	56	120	40	94	32	M10x30
K0483.55040	B	50,22	40,17	84	66	140	45	114	38	M10x35
K0483.56048	B	60,27	48,27	103	80	150	58	118	47	M12x45

